


TECHSPEC® 50 x 50mm Stabilized Wire Grid Polarizing Film

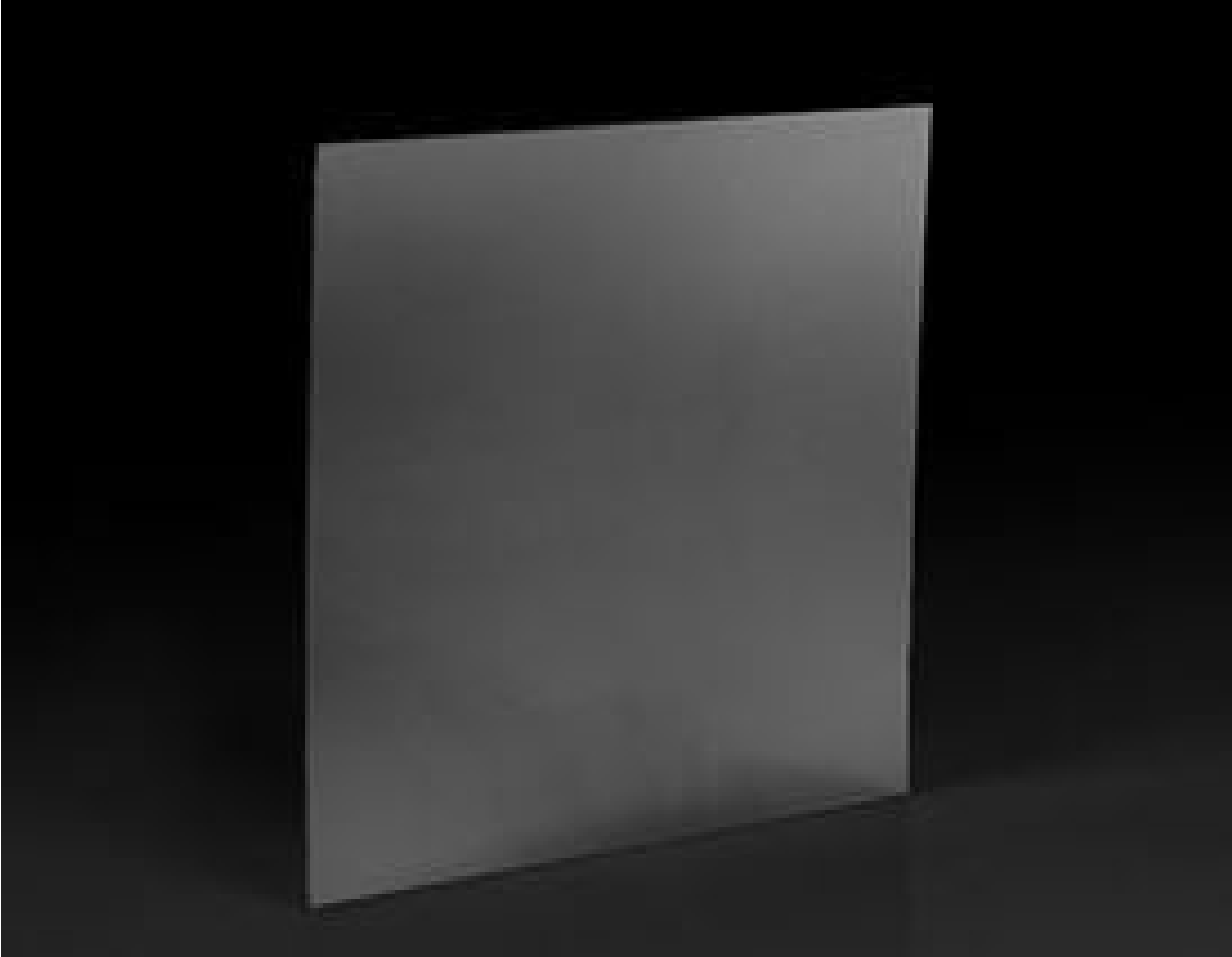

TECHSPEC® Wre Grid Polarizing Film

Stock **#20-237** ☐ In Stock

-

1

+

C\$278.60

ADD TO CART

Qty 1-10

C\$278.60

Qty 11+

C\$239.40

Volume Pricing

[Request Quote](#)

Get Product Downloads



Angle of Incidence (°):
0 - 45

Extinction Ratio:
>1415:1 @ 0° AOI, 550nm

Substrate: ☐
Aluminium Wires on COP

Operating Temperature (°C): 60 Max @90% RH 105 in dry conditions
Dimensions (mm): 50 x 50
Thickness (mm): 0.19
Thickness Tolerance (mm): ±0.030
Transmission (%): 84.9 (typical @ 550 nm)
Type: Linear Polarizer
Dimensional Tolerance (mm): ±1
Construction: Wire Grid
Wavelength Range (nm): 400 - 1200
Axis Orientation: 0° ± 1.5°, marked by Notch

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant