


50mm, Red 625nm, MicroBrite Brightfield Ring Light

See More by [Advanced Illumination](#)

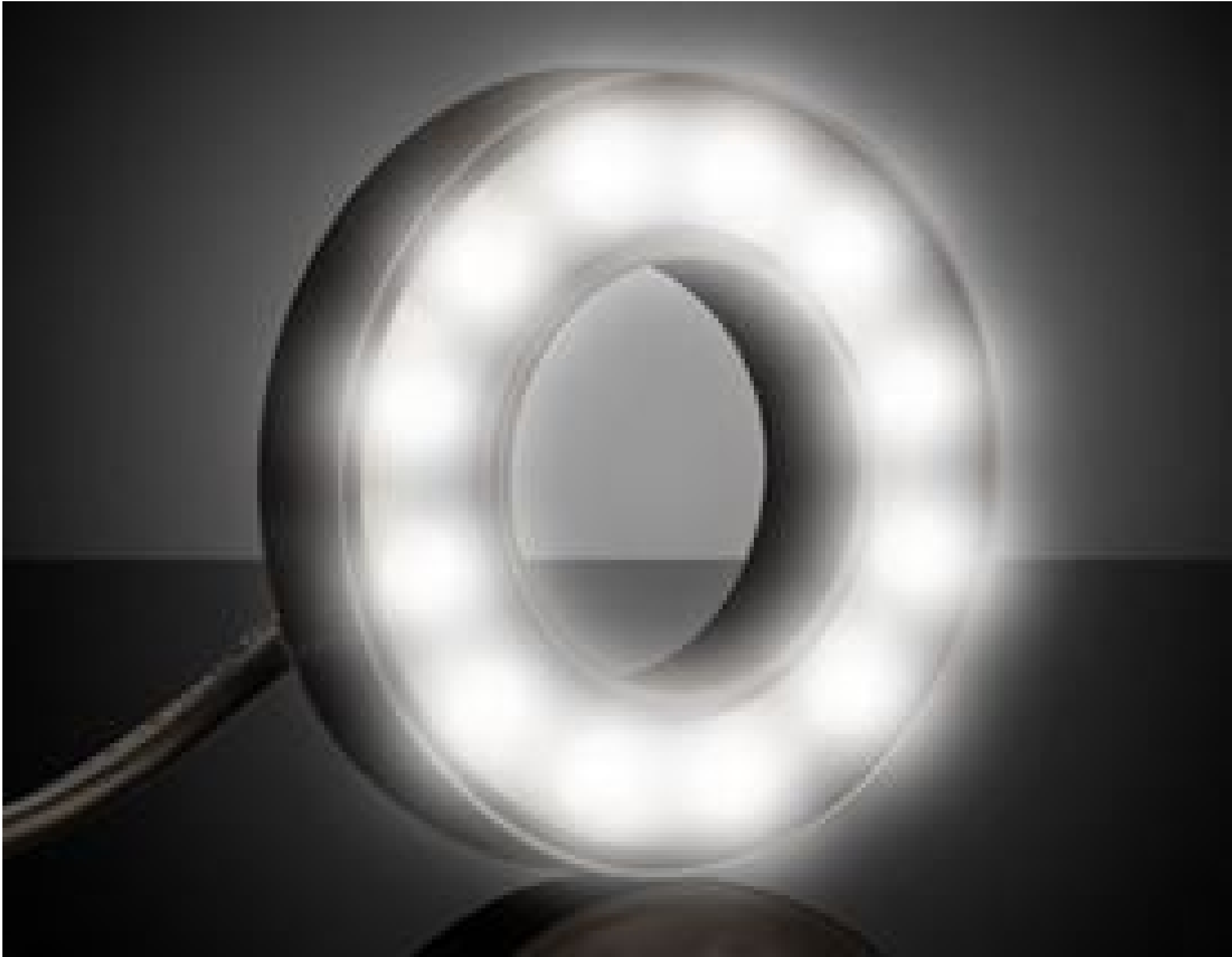

Stock **#18-568** ☐ In Stock

⊖

1

⊕

C\$1,141.00

ADD TO CART

Qty 1+
C\$1,141.00

Volume Pricing
Request Quote

Get Product Downloads

Color: Red
Height (mm): 19.09
Inner Diameter (mm): 50
Input Voltage (V): 24V
Model Number: RL208M050625IC

Operating Temperature (°C): 0 - 60
Outer Diameter (mm): 95.34
Dimensions (mm): 50.00 x 95.34 x 19.09
Mounting Threads: M4 x4
Wavelength (nm): 625.00
Weight (g): 299
LED Lifetime (hours): 50,000
Power Supply: Power Supply Required and Sold Separately. USA: #66-855 Europe: #66-855 Japan: #66-855 Korea: Not Available China: #66-855
Type of Illumination: LED Illuminator
Note: Optional Manual Intensity Adjustment #86-887 and #89-555 are Available
Manufacturer: Advanced Illumination
Geometry: Ring Light
Maximum Input Current: 0.12A
Illumination Mode: Constant
Environmental Rating: IP50

Regulatory Compliance

RoHS 2015: Exempt
Certificate of Conformance: View
Reach 233: Contains SVHC(s)