

60 x 30mm Metric Base Plate



Stock #54-975 **7 In Stock**

1

C\$84^{.00}

ADD TO CART



| Volume Pricing | |
|----------------|-------------------------------|
| Qty 1+ | C\$84.00 each |
| Need More? | Request Quote |

| Product Downloads | |
|-------------------|------------------------------|
| STEP:step | PDF Drawing:pdf |
| IGES:igs | eDrawing:eprt |
| EO Spec Sheet | Download All |


| General | |
|------------------------------------|-------------------------|
| Type: | Metric |
| Physical & Mechanical Properties | |
| Length (mm): | 60.00 |
| Width (mm): | 30.00 |
| Thickness (mm): | 7.00 |
| Center Hole: | M16 x 1.0 |
| Construction: | Black Anodized Aluminum |
| Number of Slots: | 2 |
| Threading & Mounting | |
| Mounting Threads: | (4) M2 x 0.4 |
| Regulatory Compliance | |
| RoHS 2015: | Compliant |
| Certificate of Conformance: | View |
| Reach 247: | Compliant |

Product Details

- Three Sizes Available
- Mates With Metric Posts Using Adapter [#55-036](#)
- Slotted Design for Both Metric and English Breadboards
- Mounting Holes Designed for Our Metric Line of Components
- Black Anodized Aluminum Construction

These durable and versatile breadboard mounting plates accommodate both metric and English breadboards as well as our metric line of components. Available in three sizes. Black anodized aluminum construction.

Technical Information

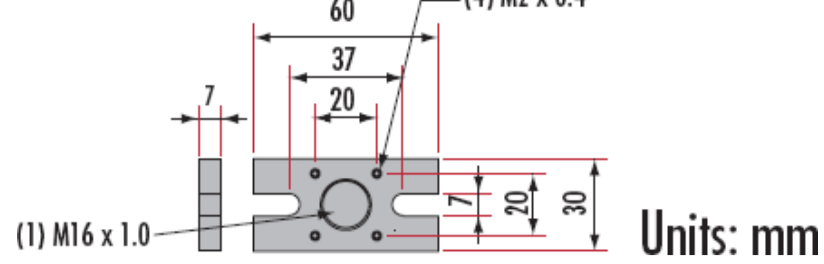

Related Products



Metric Z-Axis Stages



Metric Rotary Stages



Metric Tilt Platform



Metric Goniometers

Frequently Purchased Together



#03-655 - Sliding 2" x 3" Base Plate
C\$35.35

Qty



#03-669 - 7.0 - 67.0 Optic Height,
English Bar-Type Optic Holder
C\$162.40

Qty



#32-618 - 37mm Max. Aperture,
Iris Diaphragm
C\$132.30

Qty



#33-211 - 25mm Dia. x 100mm
FL, YAG-BBAR Coated,
Achromatic Lens
C\$179.20

Qty

Resources

Media Type

- FAQ
- Glossary
- Application Note
- Trending in Optics
- Video

? FAQ

Do you have any components that would...

? FAQ

Do your iris diaphragms have mounts for...

GLOSSARY

Axial Runout

GLOSSARY

Concentricity

GLOSSARY

Inverted Load Capacity

GLOSSARY

Tangent Arm Drive



[View More](#)

;