

TECHSPEC[®] 70mm, Side Drive, Standard Top, English Micrometer Stage



70mm, Side Drive, Solid Top, Micrometer Stage

Stock **#66-430** **5 In Stock**

-

1

+

C\$742⁰⁰

ADD TO CART

Volume Pricing	
Qty 1-2	C\$742.00 each
Qty 3+	C\$647.64 each
Need More?	Request Quote

Product Downloads

General

Type:

English

Physical & Mechanical Properties


Type of Movement:

Linear (X)


Guide System:

Crossed Roller Bearing


Drive Orientation:

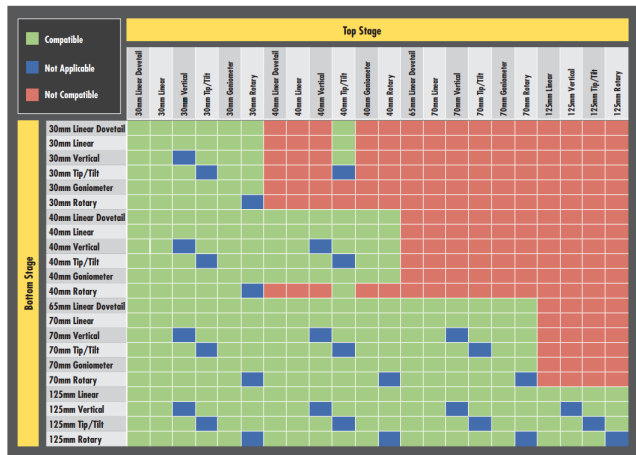


30mm Standard-Top Stages - Center Drive

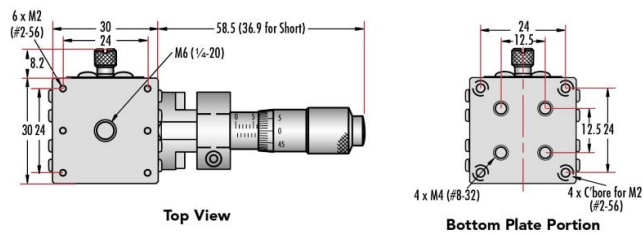


30mm Standard-Top Stages - Side Drive

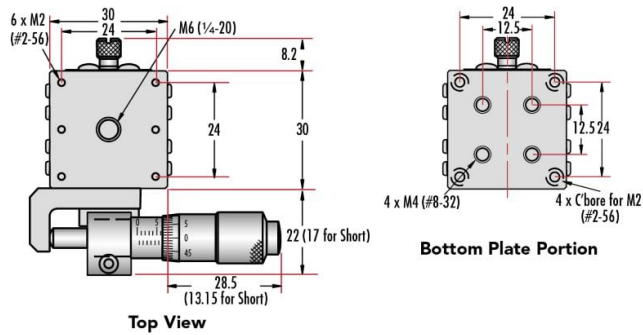


40mm Standard-Top Stages - Center Drive

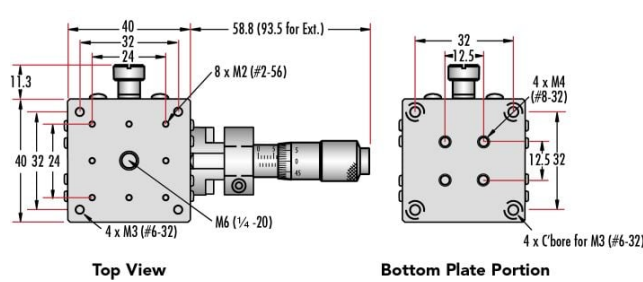


40mm Standard-Top Stages - Side Drive

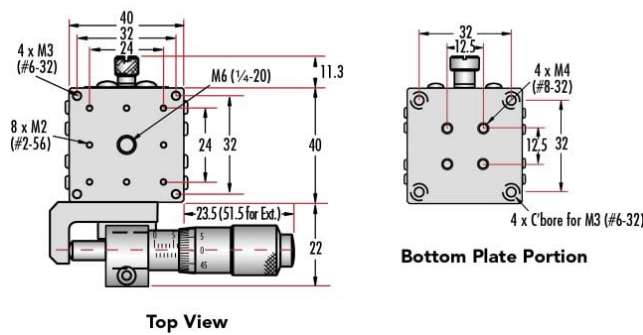


70mm Standard-Top Stages - Center Drive

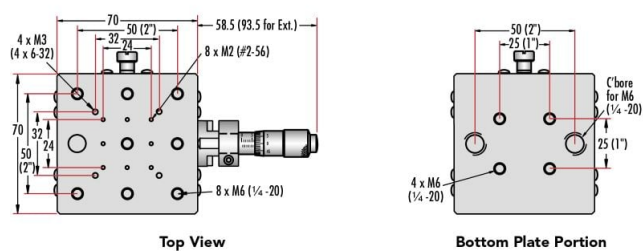

70mm Standard-Top Stages - Side Drive

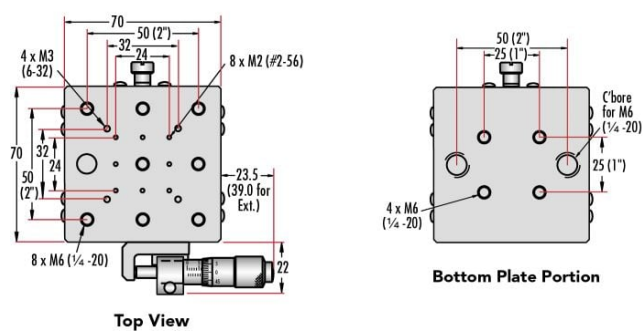

125mm Standard-Top Stages - Center Drive

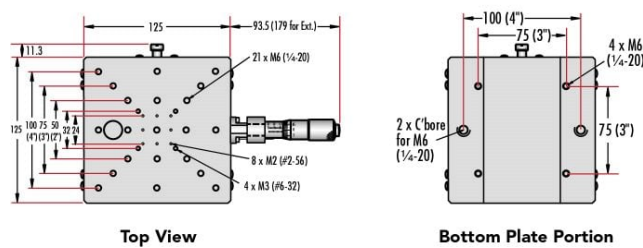

125mm Standard-Top Stages - Side Drive

