


TECHSPEC® 8mm Aperture, 100mm L Standard NA, Hexagonal Light Pipe

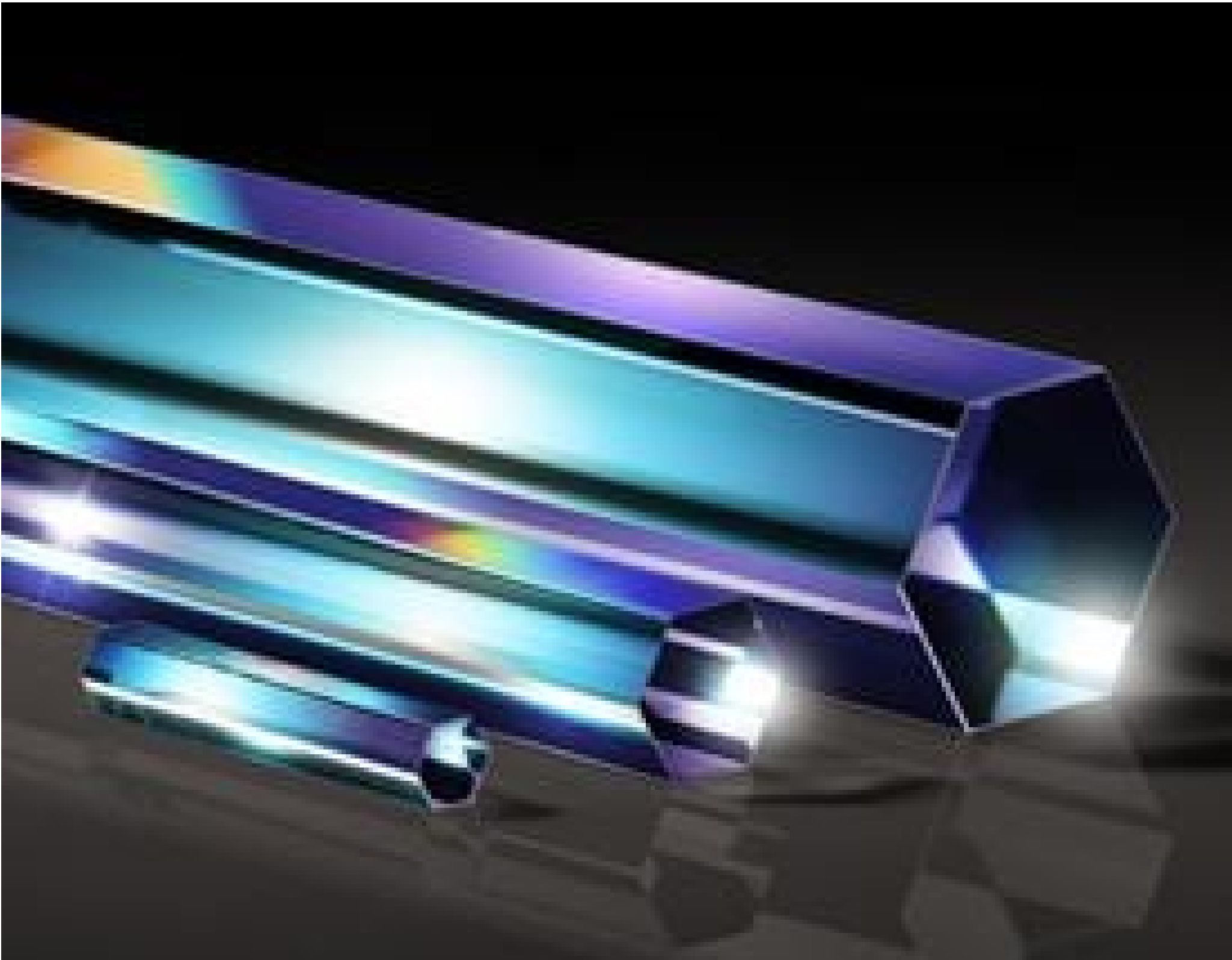

N-BK7 Light Pipe Homogenizing Rods



Stock **#49-404** ☐ In Stock

1 **C\$196.00**

ADD TO CART

Qty 1-5	C\$196.00
Qty 6+	C\$156.80
Volume Pricing	Request Quote

Get Product Downloads



Coating:
Uncoated

Substrate: ☐
[N-BK7](#)

Length (mm): 100.00
Surface Quality: 60-40
Type: Light Pipe
Entrance and Exit Aperture (mm): 8.00
Parallelism (arcmin): 5.00
Length Tolerance (mm): ±0.3
Aperture Tolerance (mm): ±0.10
Image Orientation: Light Homogenization
Light Source NA: Standard
Wavelength Range (nm): 350 - 2200
Surface Flatness (P-V): 3λ

Regulatory Compliance

RoHS 2015: Compliant
Reach 209: Compliant
Certificate of Conformance: View