


92 Grooves/mm, 12.7mm Sq, Transmission Grating Beamsplitter

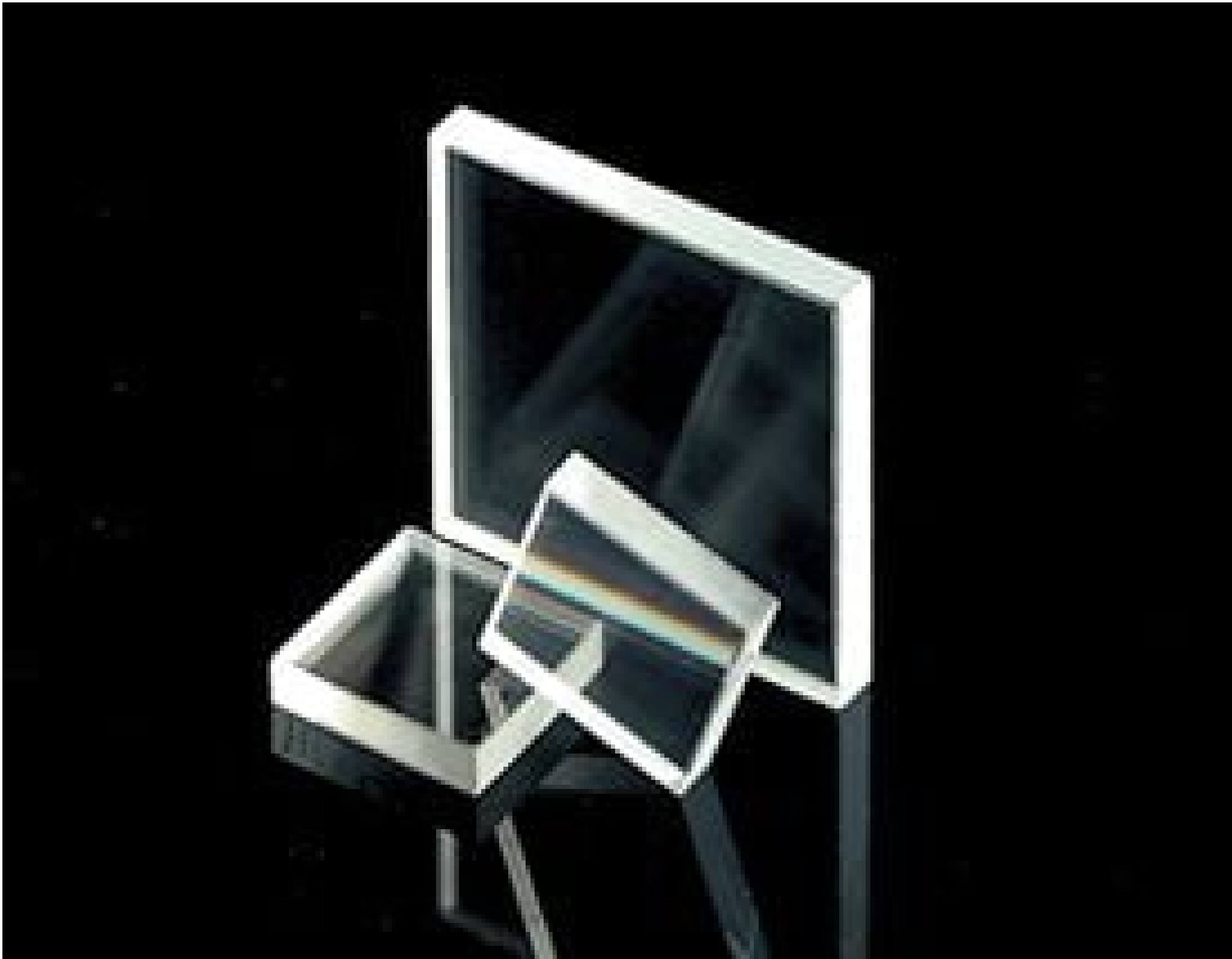

Stock **#46-071** ☐ In Stock

-

1

+

C\$182.00

ADD TO CART

Qty 1-10
C\$182.00
Qty 11+
C\$163.80
Volume Pricing
Request Quote

Get Product Downloads



Groove Density (grooves/mm):
92

Design Wavelength DWL (nm):
632.8

Dimensions (mm):
12.7 x 12.7 ±0.5

Construction: Blazed Grating
Length (mm): 12.70
Substrate:  B270
Thickness (mm): 3.00 ±0.5
Type: Transmission Diffraction Grating
Width (mm): 12.70

Regulatory Compliance

RoHS 2015: Compliant
Reach 219: Compliant
Certificate of Conformance: View
