


950nm, 6 x 6mm, OD 2.0 Longpass Filter

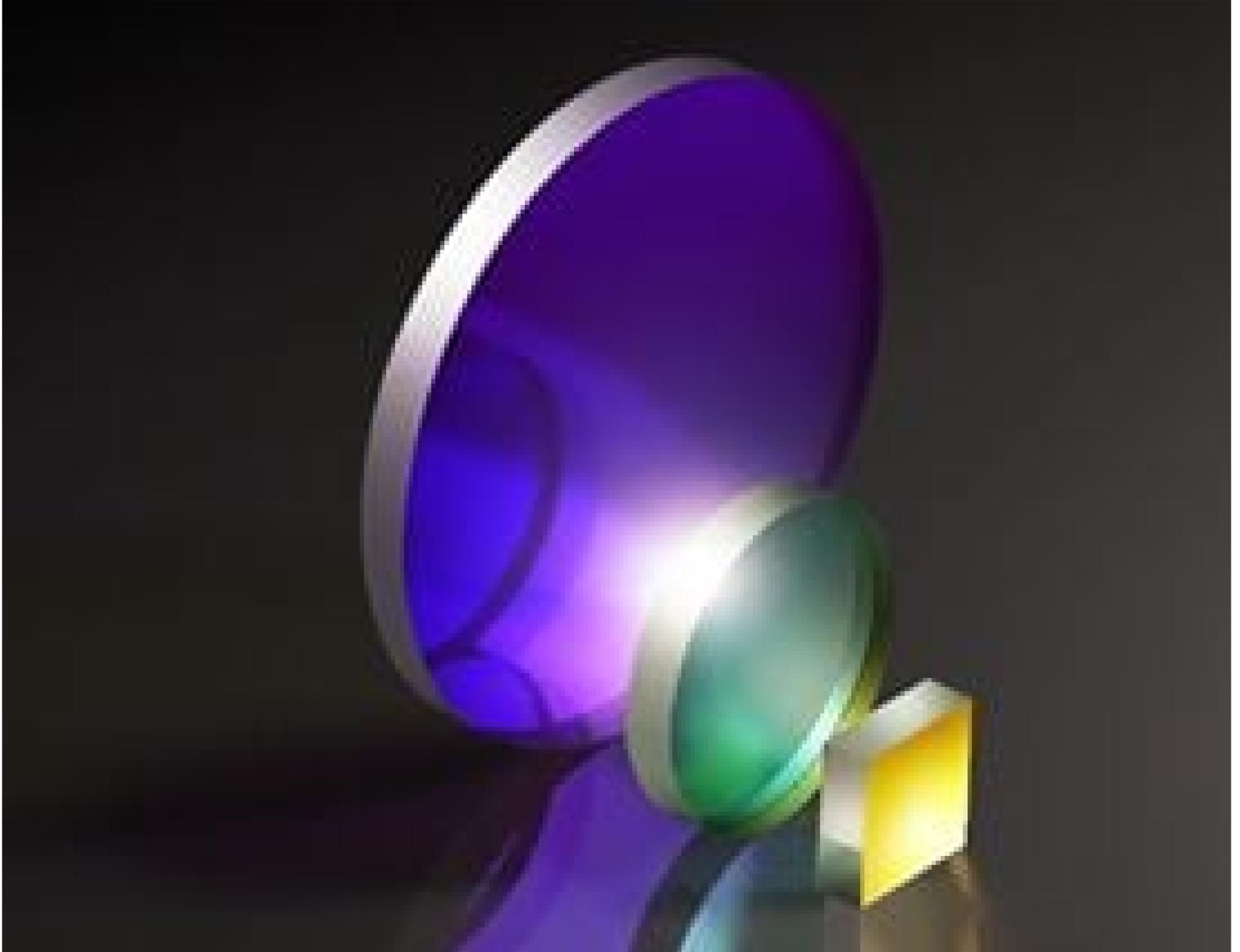

OD 2.0 Longpass Filters

Stock #15-209 In Stock

1 **C\$63.00**

ADD TO CART

Qty 1-9

C\$63.00

Qty 10+

C\$56.70

Volume Pricing

[Request Quote](#)

Get Product Downloads



Dimensions (mm):
6.00 x 6.00 +0.00/-0.20

Angle of Incidence (°):
0

Optical Density OD (Average):
≥2.0

Cut-On Wavelength (nm):
950.00 ±19

Substrate: [BOROFLOAT®](#)

Length (mm):
6.00

Coating:
Hard Coated

Rejection Wavelength (nm):
700 - 900

Surface Quality:
60-40

Thickness (mm):
2.00 ±0.10

Transmission (%):
≥85

Transmission Wavelength (nm):
990 - 1600

Type:
Longpass Filter

Width (mm):
6.00

Clear Aperture (%):
90

Environmental Durability:
ML-STD-810F, Section 507.4

Physical Durability:
ML-C-48497A, Section 3.4.1

Wavelength Range (nm):
700 - 1600

Regulatory Compliance

RoHS:
[Compliant](#)

Certificate of Conformance:
[View](#)