


Coarse/Fine Movement, 1/4-20, Rack & Pinion

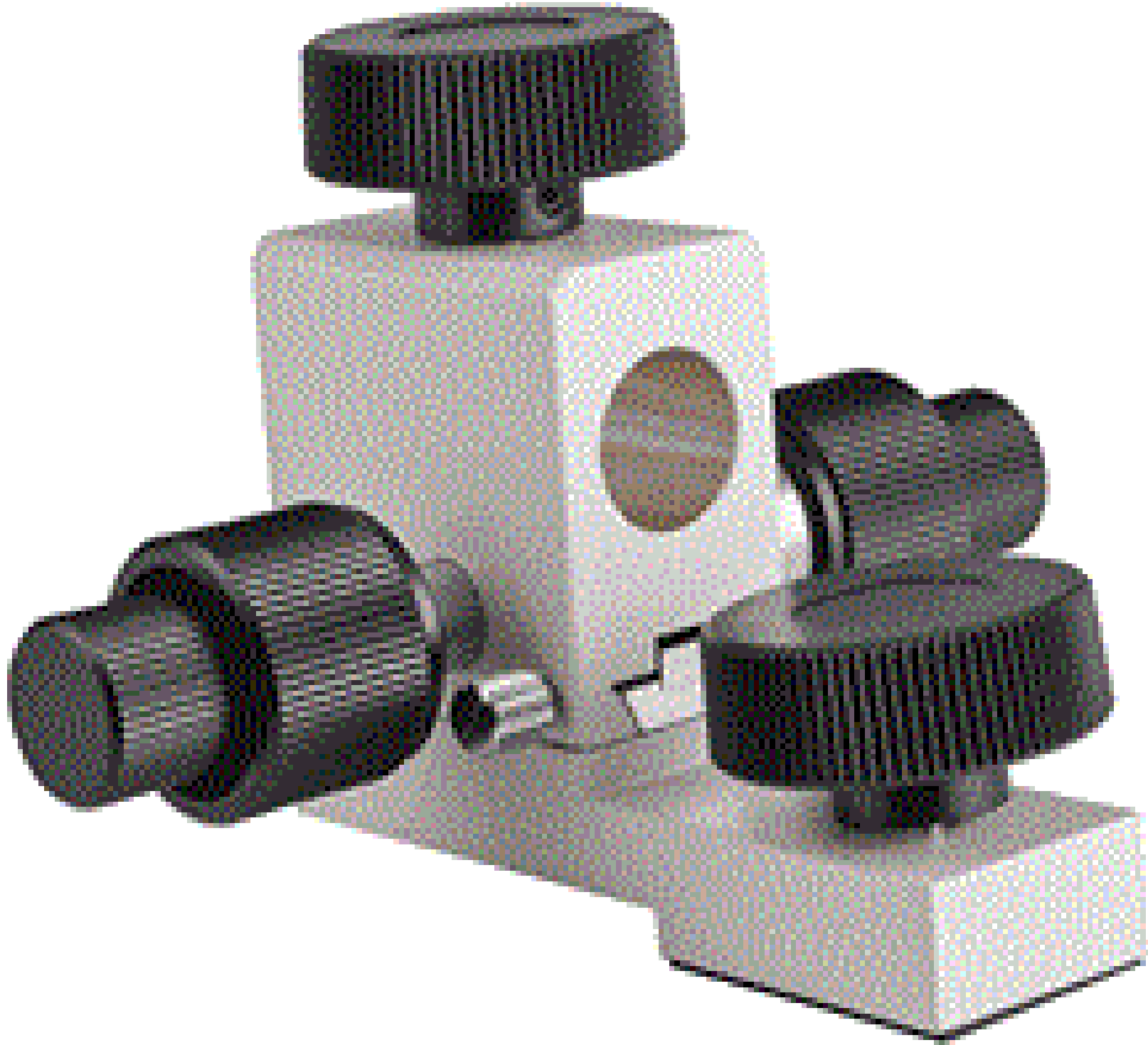

#54-794

Stock **#54-794** **3 In Stock**

- 1 + C\$812⁰⁰

ADD TO CART

Volume Pricing

Qty 1+	C\$812.00 each
Need More?	Request Quote

Product Downloads

General

Rack and Pinion Mount **Type:**

1/4-20 Stud **Note:**

Coarse/Fine Movement **Type of Adjustment:**

Physical & Mechanical Properties

Dimensions (mm):
Rack and Pinion Block: 50 H x 30 W x 50 L

2.00	Load Capacity (kg):
35 (+23/-12) in Y	Travel (mm):
25.5 coarse, 3.2 fine	Travel Per Knob Rotation (mm):
Linear (Y)	Type of Movement:
51.00	Optical Centerline from Post (mm):

Threading & Mounting

Mounting Post Hole and Thread: 3/4" Diameter Post 1/4-20 Tapped Hole

Regulatory Compliance

Exempt	RoHS 2015:
Contains SVHC(s)	Reach 224:
View	Certificate of Conformance:

Product Details

- Coarse or Fine Motion Available
- Thru Holes for Integrating Lenses
- 1/4-20 Stud for Mounting Cameras
- [Imaging System Bases](#), [Stainless Steel Posts](#), and [Accessories](#) also Available

Rack and Pinion Focusing Mounts for Imaging Systems add additional focus ability to imaging systems. Thru Holes are ideal for use with [TECHSPEC® VZM™ Zoom Imaging Lenses](#) or other imaging lenses. Rack and Pinion Movement with 1/4-20 stud can be used with any compatible camera or imaging lens. Rack and Pinion Focusing Mounts for Imaging Systems are offered with either coarse or fine motion. [Imaging System Bases](#), [Stainless Steel Posts](#), and [Accessories](#) are also available.

;