

TECHSPEC®

Mounting Clamp, 110mm Inner Diameter



Mounting Clamp, 110mm Inner Diameter, #56-027

Stock **#56-027** 20+ In Stock

-

1

+

C\$351⁴⁰

ADD TO CART

Volume Pricing	
Qty 1+	C\$351.40 each
Need More?	Request Quote

Product Downloads

General

Type:	Lens Accessory
-------	----------------

Physical & Mechanical Properties

Inner Diameter (mm):	110.0
----------------------	-------

Optical Properties


Lens Wavelength Range:	VS
------------------------	----

Regulatory Compliance	
Compliant	RoHS 2015:
Compliant	Reach 209:
View	Certificate of Conformance:


- High Resolution Telecentric Lens for Measurement and Gauging
- Up to 5 MegaPixels, 3.45µm Pixel Size Sensors
- Up to 2/3", C-Mount Telecentric Lens
- Magnification from 0.06X to 1X

TECHSPEC® GoldTL™ Telecentric Lenses were designed specifically for machine vision and metrology applications. The unique focusable design allows for working distance adjustment, while still providing <0.2° telecentricity. These lenses also feature high resolutions, low distortions, and are available for 1/2" or 2/3" sensors. TECHSPEC® GoldTL™ Telecentric Lenses have a front filter thread for easy integration of [color filters](#), [polarizers](#) or other mounted components. Both the iris and focusing adjustment positions can be fixed by set screws to remain secure in high vibration environments.


Technical Information

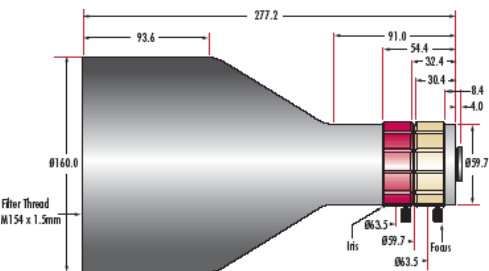


0.08X & 0.06X Telecentric Lens Units: mm

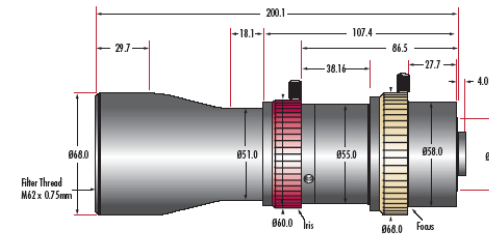

1X & 0.73X Telecentric Lenses Units: mm

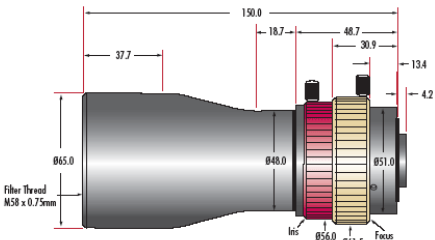

0.5X & 0.36X Telecentric Lenses

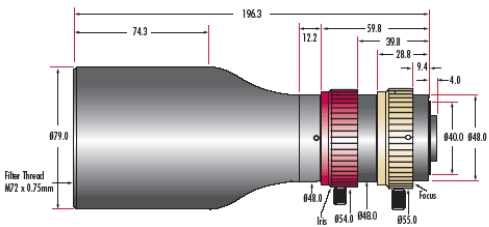

0.25X & 0.18X Telecentric Lenses Units: mm

Stock No.	A	B	C	D	E	F	G
#56-024	88mm	16mm	34mm	94mm	120mm	101.6mm	50mm
#56-025	85mm	17.5mm	32.5mm	91mm	120mm	101.6mm	48.5mm
#56-026	103mm	—	39.5mm	107mm	103mm	90mm	55.5mm
#56-027	134mm	—	55mm	148mm	134mm	122mm	81mm

