


[See all 3 Products in Family](#)

## OD 0.04 - 1.0, 50.8 x 25.4mm Stepped ND Filter

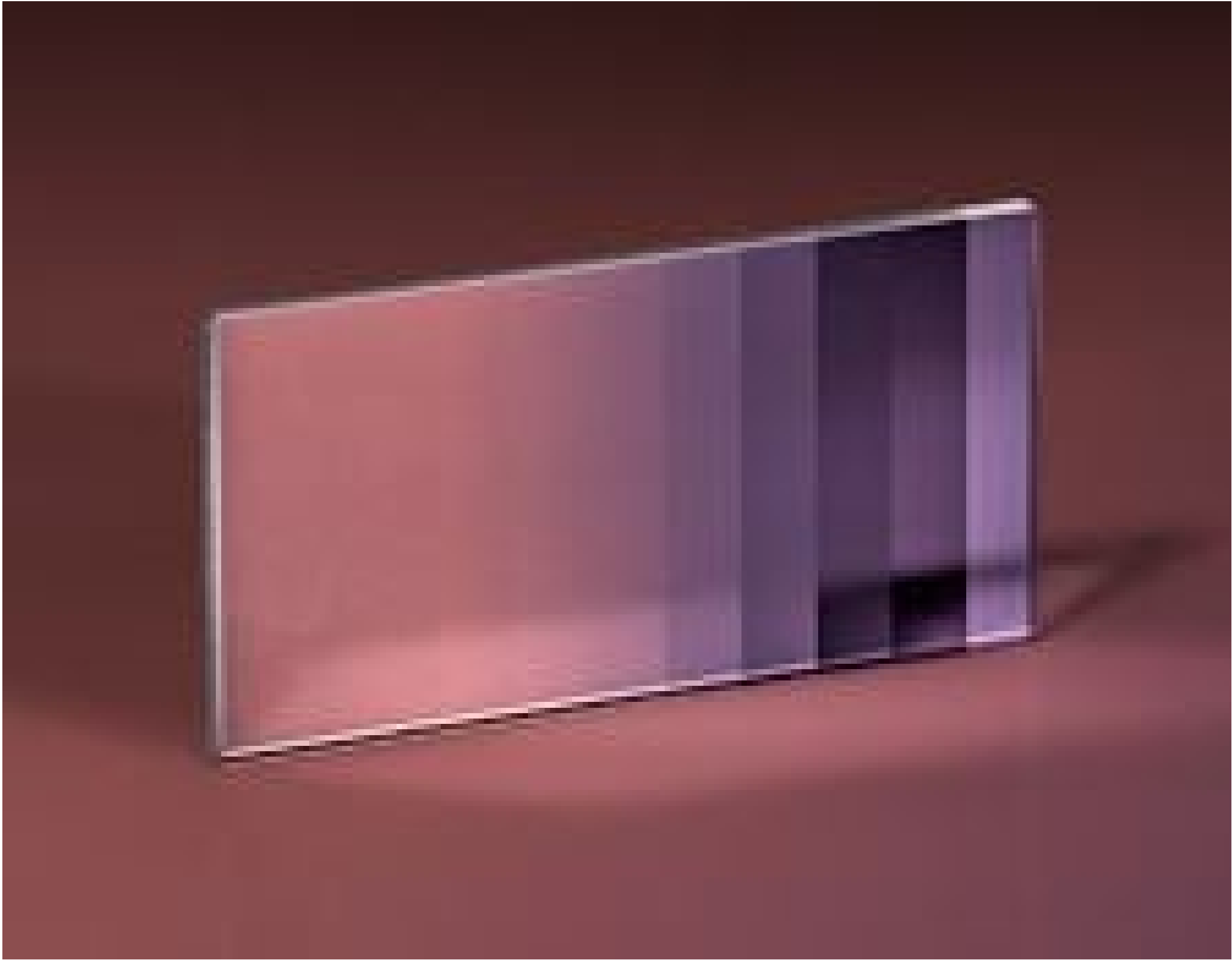

Stock **#32-599** 2 In Stock

-

1

+

C\$301<sup>.00</sup>

ADD TO CART

| Volume Pricing |                               |
|----------------|-------------------------------|
| Qty 1-10       | C\$301.00 each                |
| Qty 11-25      | C\$271.60 each                |
| Qty 26-49      | C\$259.00 each                |
| Need More?     | <a href="#">Request Quote</a> |

Product Downloads

General

Neutral Density Filter

Type:

Physical & Mechanical Properties

25.4 x 50.8

Dimensions (mm):

2.0

Length (inches):

|       |                     |
|-------|---------------------|
| 50.80 | Length (mm):        |
| 0.062 | Thickness (inches): |
| 1.0   | Width (inches):     |
| 25.40 | Width (mm):         |


| Optical Properties |                                     |
|--------------------|-------------------------------------|
| 0.04 - 1.0         | Optical Density OD (Average):       |
| Float Glass        | Substrate: <input type="checkbox"/> |
| Stepped Variable   | Coating:                            |
| 400 - 700          | Blocking Wavelength Range (nm):     |

| Regulatory Compliance |                             |
|-----------------------|-----------------------------|
| Compliant             | Reach 181:                  |
| Compliant             | RoHS 2015:                  |
| View                  | Certificate of Conformance: |

## Product Details

- 11 Discrete Density Steps
  - Design Wavelength of 400 - 700nm
  - Density Neutrality of  $\pm 5\%$
- Density and transmission vary in eleven equal steps across the surface length. The steps are abrupt changes and no light escapes between them. Spectrally flat neutral density coating. Ideal for applications requiring variable densities and known density values.

## Technical Information

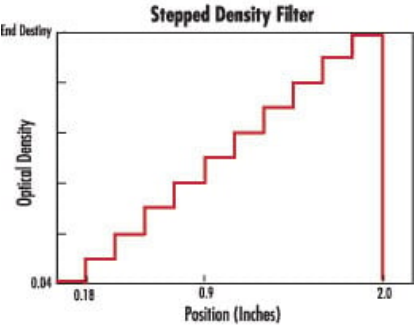

## Compatible Mounts