

# Polarizer Mount C-Thread Adapter



#87-207: Polarizer Mount C-Thread Adapter

Stock **#87-207 20+ In Stock**

-

1

+

C\$186<sup>20</sup>

ADD TO CART

| Volume Pricing |                               |
|----------------|-------------------------------|
| Qty 1-4        | C\$186.20 each                |
| Qty 5-25       | C\$167.58 each                |
| Qty 26-49      | C\$158.34 each                |
| Need More?     | <a href="#">Request Quote</a> |

Product Downloads

Threading & Mounting

Female C-Mount

Mounting Threads:

34.0

Mounting Tube Outer Diameter (mm):

Regulatory Compliance

RoHS 2015:

Product Details

- Coarse and Fine Movement Available
- Black Anodized Aluminum
- [Posts](#) and [Post Holders](#) Required for Mounting


Metric Polarizer Mounts feature secure optic retainer, lever arm for smooth rotation, locking knob for repeatability and 360° scaled vernier. [Posts](#) and [Post Holders](#) are required for mounting to a breadboard. Micrometer version provides fine adjustment. Metric Polarizer Mounts, for Micrometer Driven version only: total travel of the 0.25mm pitch fine adjustment screw is 10°. Total angular rotation per rotation of knob is 20 minutes. \*40mm total including 34mm diameter mounting tube.

Technical Information

| Diameter of Compatible Optics D | Clear Aperture CA | Drive Type | Mount Diameter A | Mount Thickness B | C  | E    | Stock No.               |
|---------------------------------|-------------------|------------|------------------|-------------------|----|------|-------------------------|
| Standard                        |                   |            |                  |                   |    |      |                         |
| 20.0                            | 17                | Standard   | 50               | 19                | 34 | 24.0 | <a href="#">#55-454</a> |
| 25.4                            | 22                | Micrometer | 69               | -                 | -  | 33.5 | <a href="#">#55-011</a> |
| 25.4                            | 22                | Standard   | 60               | 20                | 42 | 29.5 | <a href="#">#55-010</a> |
| 30.0                            | 27                | Micrometer | 69               | -                 | -  | 33.5 | <a href="#">#57-570</a> |
| 30.0                            | 27                | Standard   | 60               | 20                | 42 | 29.5 | <a href="#">#57-569</a> |
| 50.0                            | 47                | Micrometer | 89               | -                 | -  | 43.5 | <a href="#">#56-329</a> |
| 50.0                            | 47                | Standard   | 80               | 20                | 62 | 39.5 | <a href="#">#55-455</a> |
| Glan-Thompson Polarizer Mounts  |                   |            |                  |                   |    |      |                         |
| 25.4                            | 18                | Micrometer | 69               | -*                | -  | 33.5 | <a href="#">#57-572</a> |
| 25.4                            | 18                | Standard   | 60               | 20*               | 42 | 29.5 | <a href="#">#57-571</a> |


Polarizer Mounts

Standard

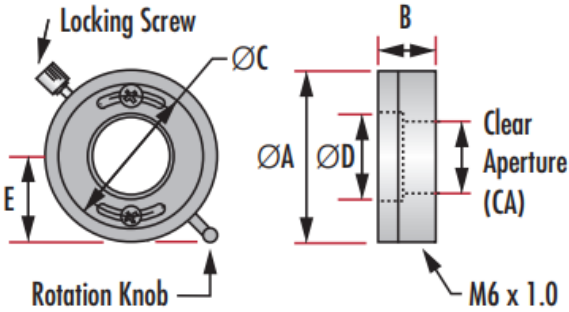


Glan-Thompson Mount

Standard

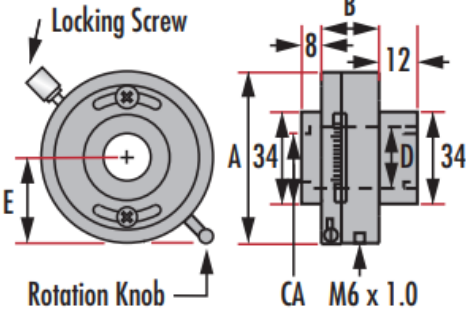

Micrometer Driven

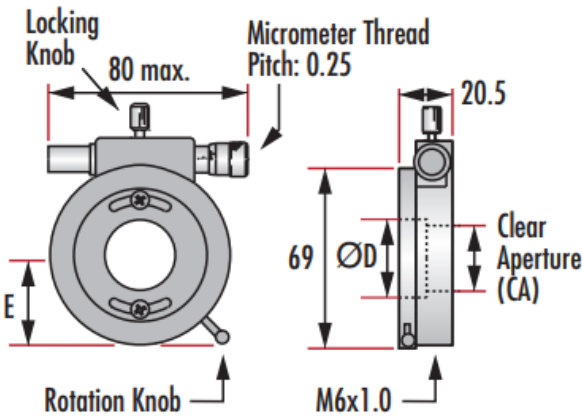

Micrometer Driven

