 



Hoya RT830 (IR) 12mm Dia., Colored Glass Bandpass Filter

See More by [Hoya](#)

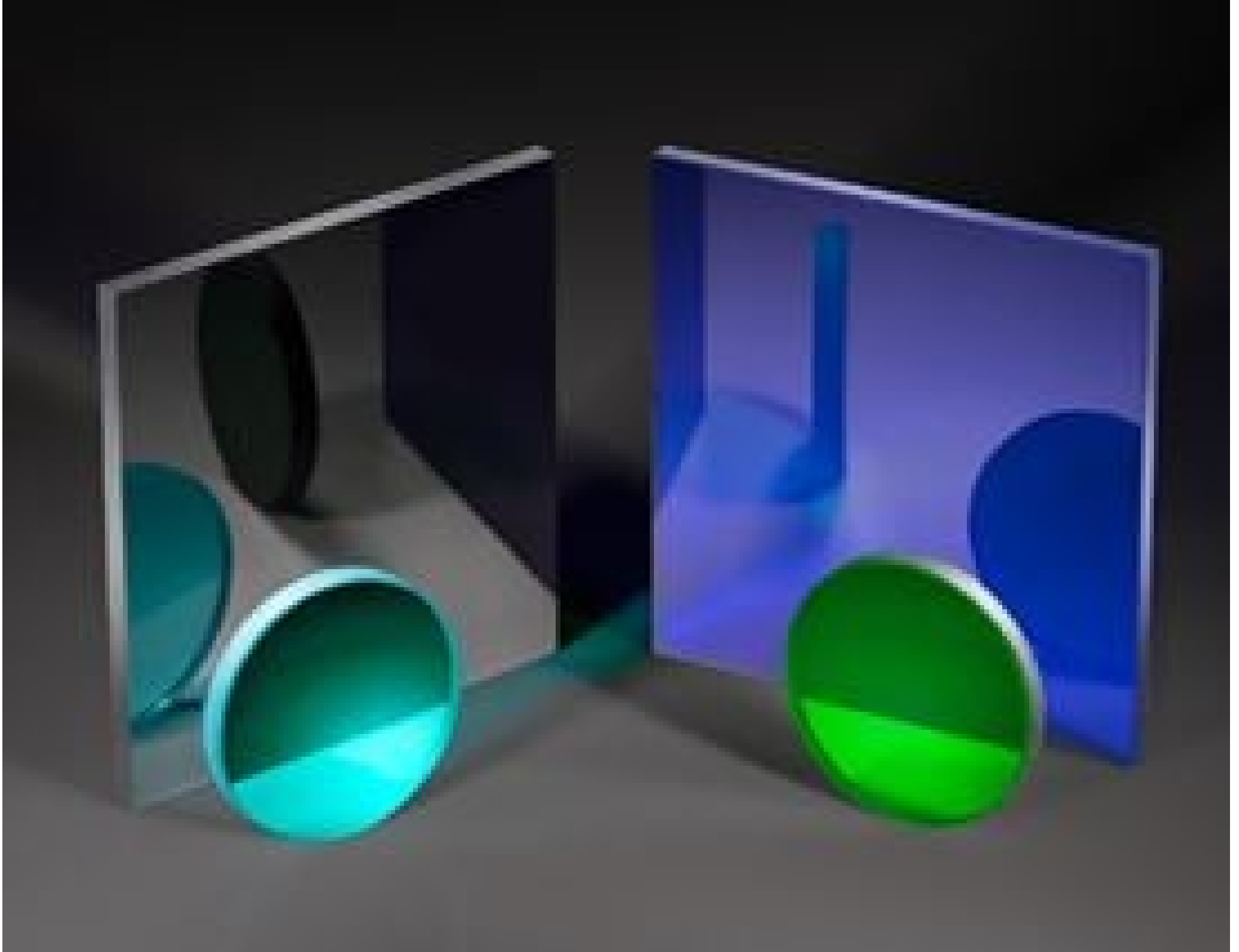

Stock #46-082 In Stock

[Additional Bandwidths](#)

1 **C\$51.80**

ADD TO CART

Qty 1-10

C\$51.80

Qty 11+

C\$46.20

Volume Pricing

[Request Quote](#)

Get Product Downloads



Diameter (mm):
12.00

Center Wavelength CWL (nm):
830.00

Density (g/cm³):
2.75

Full Width-Half Max FWHM (nm):
260.00

Glass/Filter Number:
[Hoya RT830](#)

Substrate:
Colored Glass

Coating:
Uncoated

Color:
Black

Surface Quality:
60-40

Thickness (mm):
2.50

Thickness Tolerance (mm):
±0.2

Type:
Bandpass Filter

Wavelength:
IR

Parallelism (arcmin):
≤1

Dimensional Tolerance (mm):
+0/-0.25

Regulatory Compliance

RoHS 2015:
[Exempt](#)

Reach 224:
[Compliant](#)

Certificate of Conformance:
[View](#)