 



SCHOTT BG39, 12.5mm Dia., 1mm Thick, Colored Glass Bandpass Filter

See More by [SCHOTT Optical Components](#)

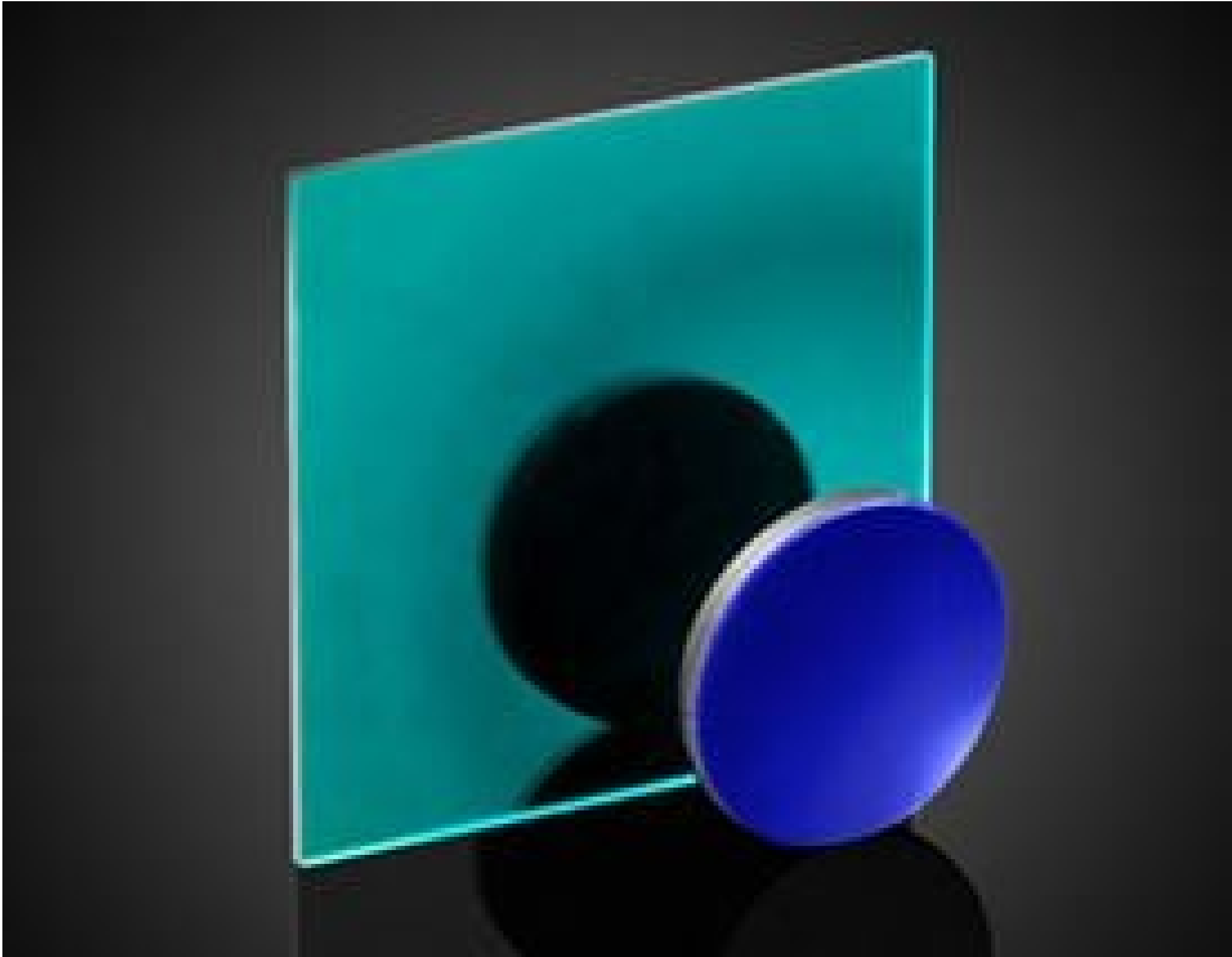

Stock **#16-366** ☐ In Stock

☐ [Additional Bandwidths](#)

-

1

+

C\$57.40

ADD TO CART

Qty 1-10

C\$57.40

Qty 11+

C\$51.80

Volume Pricing

[Request Quote](#)

Get Product Downloads

Diameter (mm):
12.50

Center Wavelength CWL (nm):
507.00

Density (g/cm³): 2.74
Glass/Filter Number: SCHOTT BG39
Coating: Uncoated
Color: Blue-Green
Index of Refraction n_d: 1.54
Surface Quality: 60-40
Transformation Temperature (°C): 322
Thickness (mm): 1.00 ±0.1
Type: Bandpass Filter
Wavelength: VIS
Bevel: Protective as needed

Regulatory Compliance

Certificate of Conformance: View
--