

5.0 - 100.0mm Optic Dia., Self-Centering Jaw Clamp



Self-Centering Jaw Clamps

Stock **#16-078** **7 In Stock**

-

1

+

C\$574⁰⁰

ADD TO CART

Volume Pricing	
Qty 1-4	C\$574.00 each
Qty 5+	C\$506.52 each
Need More?	Request Quote

Product Downloads

General

Fixed	Type:
Circular	Type of Optics:

Physical & Mechanical Properties

166	Height (mm):
	Outer Diameter (mm):

138	
	Weight (lbs):
0.68	
	Construction:
Black Anodized Aluminum	
Threading & Mounting	
	Size of Compatible Optics (mm):
5.0 - 100.0	
	Compatible Post:
M6 x 1.0, 1/4-20	

Regulatory Compliance	
	RoHS 2015:
Compliant	
	Certificate of Conformance:
View	
	Reach 247:
Compliant	

Product Details


• Two Mount Sizes Available, for 4mm-36mm and 5mm-100mm Dia. Optics

• Optical Centerline Remains Constant Regardless of Optical Diameter

• Mounts Feature Both Metric and English Tapped Mounting Holes

Self-Centering Jaw Clamps are ideal for easily interchanging optics of different diameters in a system while maintaining a constant optical centerline of the system. Mounts are available for either mounting 4mm to 36mm diameter optics ([#16-077](#)) or 5mm to 100mm diameter optics ([#16-078](#)). The small jaw clamp features both M4 x 0.7 and 8-32 tapped mounting holes, while the large jaw clamp features both M6 x 1.0 and 1/4"-20 tapped mounting holes. The stainless-steel tipped jaws feature a v-groove to help vertical alignment of thinner optics. Self-Centering Jaw Clamps are directly mountable to [TECHSPEC® Stainless Steel Mounting Posts](#) and [Pedestal Posts](#).

Technical Information

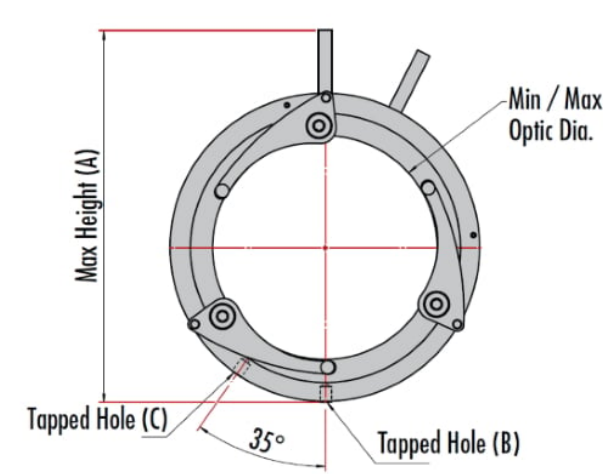

Outer Diameter (mm)	Min. Optic Diameter (mm)	Max. Optic Diameter (mm)	A (mm)	B	C	Stock No.
58	4	36	74	#8-32	M4 x 0.7	#16-077
138	5	100	166	1/4-20	M6 x 1.0	#16-078