 



Hoya U360 (UV) 25.4mm Dia., Colored Glass Bandpass Filter

See More by [Hoya](#)

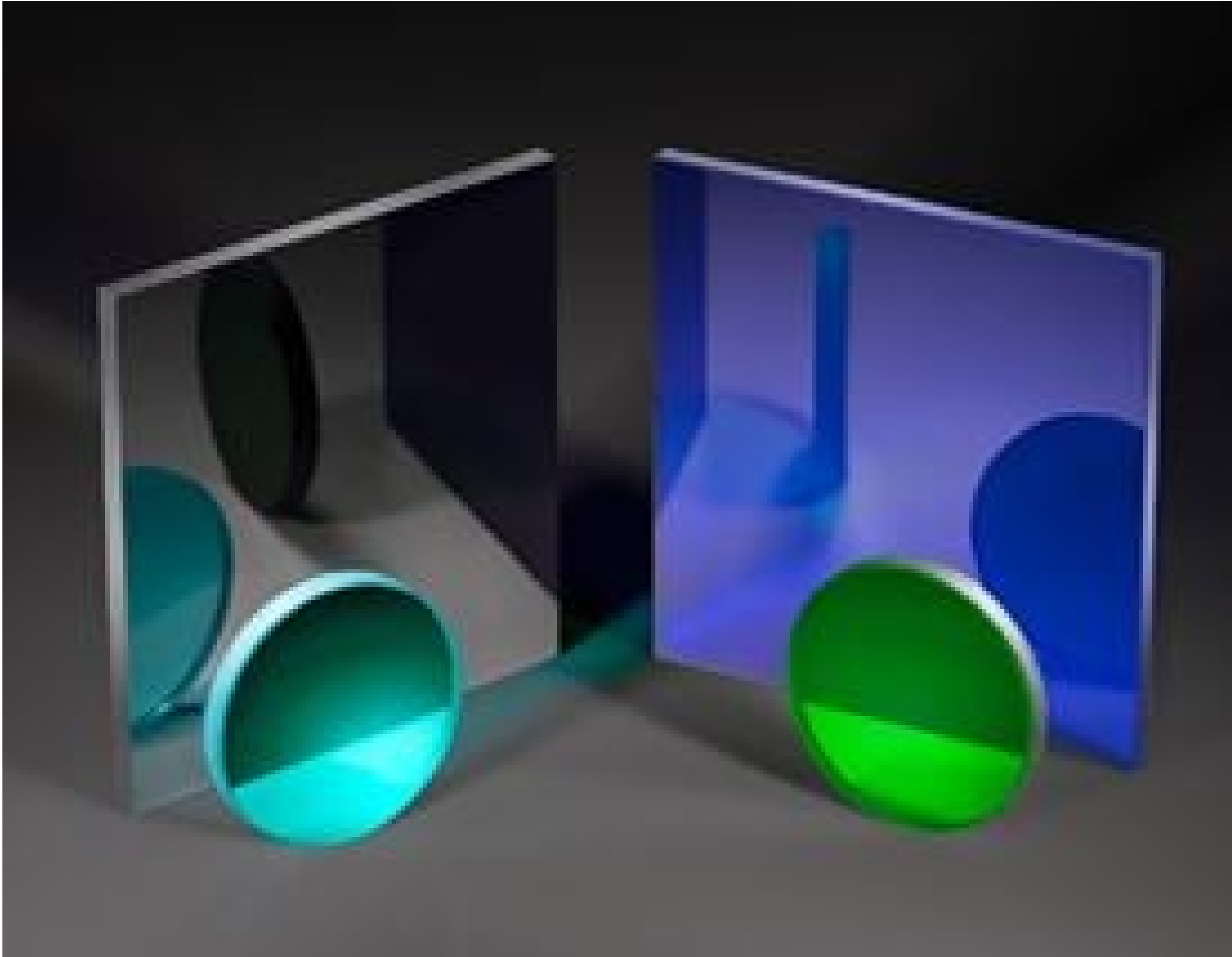

Stock **#46-441** ☐ In Stock

☐ [Additional Bandwidths](#)

-

1

+

C\$110.60

ADD TO CART

Qty 1-10

C\$110.60

Qty 11+

C\$98.00

Volume Pricing

[Request Quote](#)

Get Product Downloads



Diameter (mm):
25.40

Center Wavelength CWL (nm):

360.00
Density (g/cm³): 2.74
Full Width-Half Max FWHM (nm): 45.00
Glass/Filter Number: Hoya U360
Substrate: ☐ Colored Glass
Coating: Uncoated
Color: Black
Surface Quality: 60-40
Thickness (mm): 2.50
Thickness Tolerance (mm): ±0.2
Type: Bandpass Filter
Wavelength: UV
Parallelism (arcmin): ≤1
Dimensional Tolerance (mm): +0/-0.25

Regulatory Compliance

RoHS 2015: Exempt
Reach 224: Compliant
Certificate of Conformance: View