


Variable Frequency Target 5-120 lp/mm

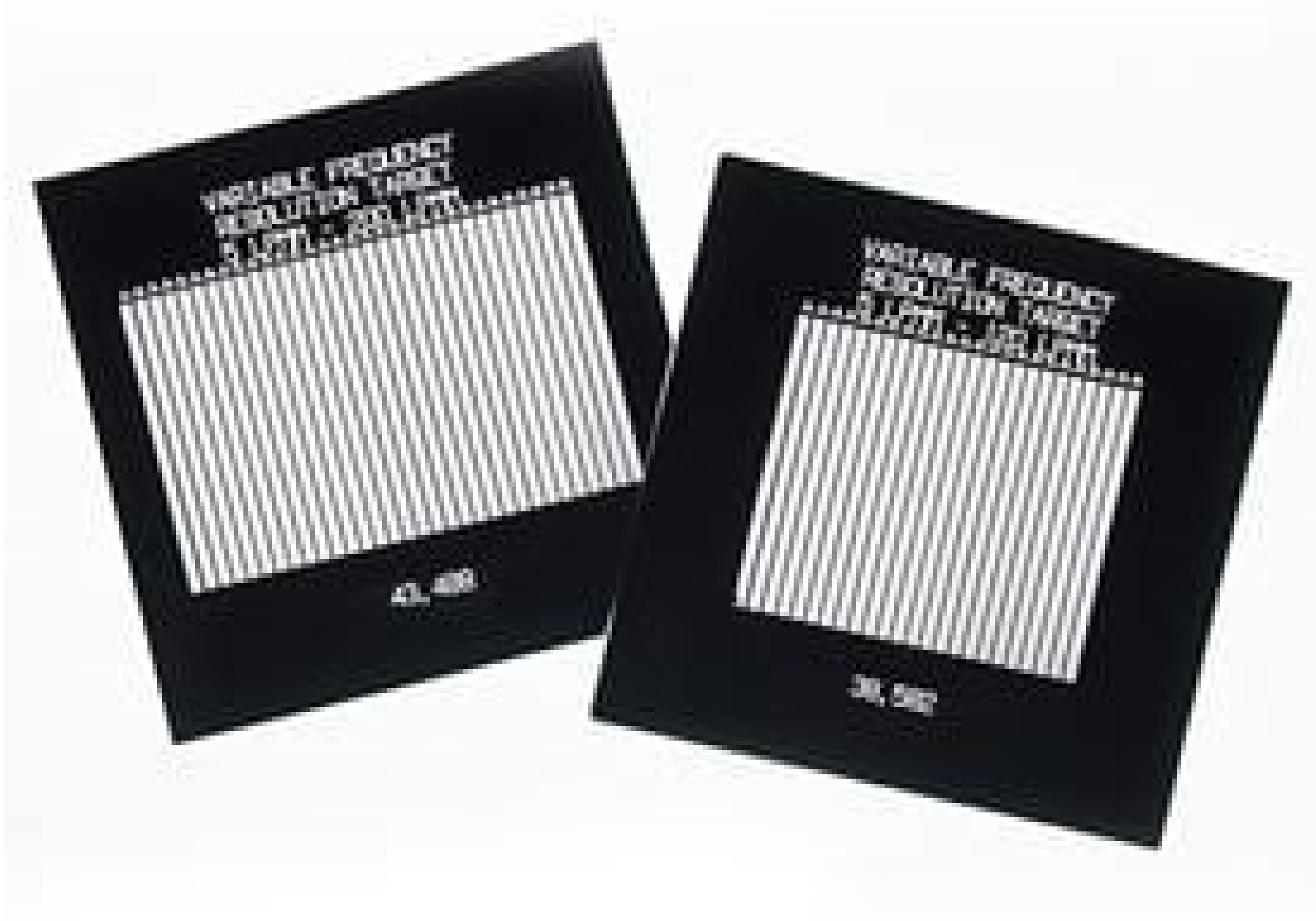

Stock **#38-582** CLEARANCE **8 In Stock**

-

1

+

C\$1,036^{.00}

ADD TO CART

Volume Pricing	
Qty 1-4	C\$1,036.00 each
Qty 5+	C\$985.04 each
Need More?	Request Quote

Product Downloads

Physical & Mechanical Properties	
25.4 x 29.85	Pattern Size (mm):
2 x 2	Dimensions (inches):
1.50	Thickness (mm):
Beveled	Edges:

Flatness (mm):

0.00254

Optical Properties

Vacuum deposited durable chromium

Coating:

Float Glass

Substrate:

≥3.0

Optical Density OD (Average):

40-10

Surface Quality:

Regulatory Compliance

Compliant

RoHS 2015:

View

Certificate of Conformance:

Compliant

Reach 240:

Product Details

- 5 lp/mm to 120 lp/mm or 5 lp/mm to 200 lp/mm
- 1mm Wide Step Size
- 5 lp/mm Step Increments
- Used to Calibrate Video Systems
- Inspect Unknown Resolutions

Variable frequency targets are excellent for evaluating resolution, field distortion, and parfocal stability.